

Centrix™ Splice Cassette 24x SC/UPC adapters and 24x SC/UPC single fiber pigtails (OS2) HS

CORNING

Part Number:
CTXCPP24-3C-2RH000

The Centrix™ splice cassette provides 24 LC APC single fiber ports. The cassette is loaded with 12 LC Duplex APC adapters, colored LC single fiber pigtails and accepts crimp or heat-shrink splice protectors. A drop handle provide fiber port protection, patch cord organization and labeling on front and top of the cassette. The cassette is slidable in Centrix housings and is secured with a latch mechanism. The jumper guide direction is to the left side of the cassette but can simply be changed with accessories to the right. The transparent and captive top and bottom cover enable easy handling and visual inspection or trouble shooting. The multiple tube entry points on the cassette provide flexible loading of buffer tubes and bare fibers in the cassette.

Features and Benefits

Easy port access and identification

Easy port access and identification

Integrated patch cord guide supports patch management

Front and top labeling for easy identification


Fiber identification with VFL (visual fault location) in the adapter

Captive covers on both sides of the cassette

Transparent covers enable trouble shooting

Bare fiber and tube slack storage up to 2m by design

Multiple tube entry from the rear or both sides on the cassette

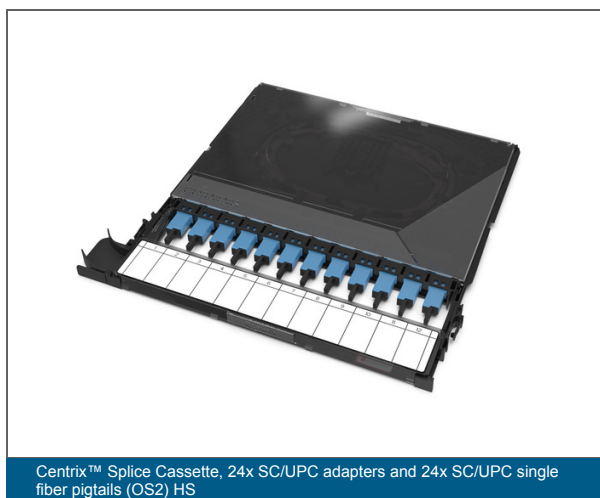

Centrix™ Splice Cassette, 24x SC/UPC adapters and 24x SC/UPC single fiber pigtails (OS2) HS

Centrix™ Splice Cassette 24x SC/UPC adapters and 24x SC/UPC single fiber pigtails (OS2) HS

CORNING

Specifications

General Specifications

Product Type	Centrix™
Fiber Category	Single-mode (OS2)
Cable Type	250 µm

Standards

RoHS	Free of hazardous substances according to RoHS 2011/65/EU
------	---

Environmental Conditions

Temperature Range, Operation	-40 °C to 70 °C (-40 °F to 158 °F)
------------------------------	-------------------------------------

Design

Pigtail Type	900 µm
Number of Ports	24

Design - Adapter

Housing Color	Blue
Adapter Type	SC

Optical Specification - Hardware

Insertion Loss	≤ 0.25 dB
Min. Reflectance	-58 dB

Connector Specs

Polish	UPC
--------	-----

Centrix™ Splice Cassette 24x SC/UPC adapters and 24x SC/UPC single fiber pigtails (OS2) HS



Connector Specs	
Connector Type	SC

Dimensions	
Weight	0.5 kg

Ordering Information	
Product Number	CTXCPP24-3C-2RH000
Shipping Weight	0.85 kg
Units per Delivery	1/1



Corning Optical Communications LLC • 4200 Corning Place • Charlotte, NC • 28216 • United States
800-743-2675 • FAX: 828-325-5060 • International: +1-828-901-5000 • www.corning.com/opcomm

A complete listing of the trademarks of Corning Optical Communications is available at www.corning.com/opcomm/emea/trademarks. Corning Optical Communications is ISO 9001 and ISO 14001 certified. © 2026 Corning Optical Communications. All rights reserved.