

Centrix® Splice Cassette 24x SC/APC adapters and 24x SC/APC single fibre pigtails (OS2) HS



Part Number:
CTXCPP24-6C-2RH000

The Centrix® splice cassette provides 24 LC APC single fibre ports. The cassette is loaded with 12 LC Duplex APC adapters, colored LC single fibre pigtails and accepts crimp or heat-shrink splice protectors. A drop handle provide fibre port protection, patch cord organization and labeling on front and top of the cassette. The cassette is slidable in Centrix® housings and is secured with a latch mechanism. The jumper guide direction is to the left side of the cassette but can simply be changed with accessories to the right. The transparent and captive top and bottom cover enable easy handling and visual inspection or trouble shooting. The multiple tube entry points on the cassette provide flexible loading of buffer tubes and bare fibres in the cassette.

Features and Benefits

Easy port access and identification

Easy port access and identification

Integrated patch cord guide supports patch management

Front and top labeling for easy identification


Fibre identification with VFL (visual fault location) in the adapter

Captive covers on both sides of the cassette

Transparent covers enable trouble shooting

Bare fibre and tube slack storage up to 2m by design

Multiple tube entry from the rear or both sides on the cassette

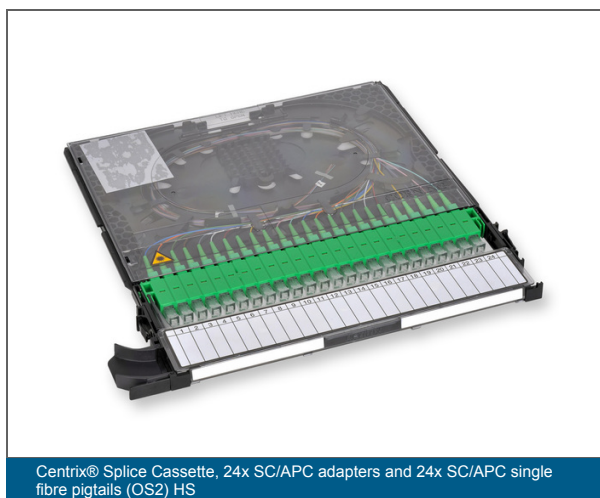

Centrix® Splice Cassette, 24x SC/APC adapters and 24x SC/APC single fibre pigtails (OS2) HS

Centrix® Splice Cassette 24x SC/APC adapters and 24x SC/APC single fibre pigtails (OS2) HS



Specifications

General Specifications	
Fibre category	Single-mode (OS2)
Cable type	250 µm

Standards	
RoHS	Free of hazardous substances according to RoHS 2011/65/EU

Environmental Conditions	
Temperature range, operation	-40 °C to 70 °C

Design	
Pigtail type	900 µm
Number of ports	24

Design - Adapter	
Adapter housing colour	Green
Adapter type	SC

Optical Specification - Hardware	
Insertion Loss	≤ 0.25 dB
Min. Reflectance	-65 dB

Dimensions	
Weight	0.5 kg

Centrix® Splice Cassette 24x SC/APC adapters and 24x SC/APC single fibre pigtails (OS2) HS



Ordering Information	
Product Number	CTXCPP24-6C-2RH000
Shipping weight	0.85 kg
Units per delivery	1/1



Corning Optical Communications GmbH & Co. KG • Leipziger Strasse 121 • 10117 Berlin, Germany
00 800 2676 4641 • FAX: • www.corning.com/opcomm/emea

A complete listing of the trademarks of Corning Optical Communications is available at www.corning.com/opcomm/emea/trademarks. Corning Optical Communications is ISO 9001 and ISO 14001 certified. © 2026 Corning Optical Communications. All rights reserved.