

Centrix™ loaded housing 4U, 12 cassettes, 24xSC/APC adapters + SF pigtails, 288 ports, HS

CORNING

Part Number:
CX4U8P24-6C-2RH000

A Centrix™ System 4U housing holds 12 cassettes. Housings can be ordered with cassettes for on-frame splicing. At the foundation of the Centrix System is a single, modular cassette that can be tailored to include a variety of optical devices (splitter, WDM, etc). The modular cassette provides flexibility and functionality within a single frame without sacrificing density. Each cassette contains up to either 24 SC or 36 LC connector adapters. Easy port access is possible due to a sliding cassette with drop-down handle.

Features and Benefits

Loaded housing with 288 SC/APC Ports ready for splicing

Faster system setup and reduced packaging material

300mm depth for installation in telco cabinets

Easy port access and identification

Easy port access and identification

Integrated patch cord guide supports patch management


Front and top labeling for easy identification

Fiber identification with VFL (visual fault location) in the adapter

Captive covers on both sides of the cassette

Multiple tube entry from the rear or both sides on the cassette

Bare fiber and tube slack storage up to 2m by design

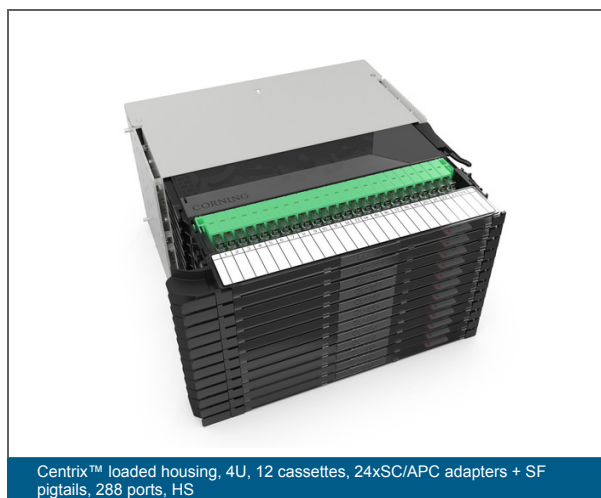

Centrix™ loaded housing, 4U, 12 cassettes, 24xSC/APC adapters + SF pigtails, 288 ports, HS



Centrix™ loaded housing, 4U, 12 cassettes, 24xSC/APC adapters + SF pigtails, 288 ports, HS

Centrix™ loaded housing 4U, 12 cassettes, 24xSC/APC adapters + SF pigtails, 288 ports, HS



Centrix™ loaded housing, 4U, 12 cassettes, 24xSC/APC adapters + SF pigtails, 288 ports, HS

Specifications

General Specifications	
Product Type	Housings
Fiber Category	Single-mode (OS2)
Standards	
RoHS	Free of hazardous substances according to RoHS 2011/65/EU
Environmental Conditions	
Temperature Range, Operation	-40 °C to 70 °C (-40 °F to 158 °F)
Design	
Number of ports - cut	288
Pigtail Type	900 μm

Centrix™ loaded housing 4U, 12 cassettes, 24xSC/ APC adapters + SF pigtails, 288 ports, HS

CORNING

Design

Number of Ports	288
-----------------	-----

Specifications - Connector A

Connector Type	SC
Polish	APC

Specifications - Connector B

Connector Type	SC
Polish	APC

Dimensions

Height	178 mm (7.01 in)
Width	340 mm (13.39 in)
Depth	290 mm (11.42 in)
Weight	10.5 kg

Ordering Information

Product Number	CX4U8P24-6C-2RH000
Height Unit	4 U
Shipping Weight	11.2 kg
Shipping Height	520 cm
Shipping Width	265 mm (10.43 in)
Shipping Depth	500 cm
Units per Delivery	1/1

Centrix™ loaded housing 4U, 12 cassettes, 24xSC/ APC adapters + SF pigtails, 288 ports, HS

CORNING



Corning Optical Communications LLC • 4200 Corning Place • Charlotte, NC • 28216 • United States
800-743-2675 • FAX: 828-325-5060 • International: +1-828-901-5000 • www.corning.com/opcomm

A complete listing of the trademarks of Corning Optical Communications is available at www.corning.com/opcomm/trademarks. All other trademarks are the properties of their respective owners. Corning Optical Communications is ISO 9001 certified. © 2026 Corning Optical Communications. All rights reserved.