

Splice Closure Fiber (SCF) 72 single-fiber splice capacity, 4-in diameter, 18-in dome length, 3 drop ports, without splice trays

CORNING

Part Number: SCF-4C18-01

Corning Splice Closure (SCF) with Mechanical End Cap is designed for splicing fibers in aerial, duct, and buried applications. These sealed canister closures are available in configurations that can accommodate from 72 to 576 single-fiber splices, or from a 288- to 1296-fiber capacity if splicing ribbons.

The consolidation of multiport tails for up to 24 flat cables is accomplished with optional add-a-cable kits. Designed for configuration flexibility, these closures offer expanded slack storage, various tray heights, and mass-platform storage.

Features and Benefits

Sealed butt-style closure

Environmental protection

Modular fiber management system


Preserve the ease of traditional (flat) ribbon splicing while gaining simplified ribbon fiber routing

Increased splicing capability in the field

Aerial, wall, pole, direct

Suitable for all applications

Environmental protection

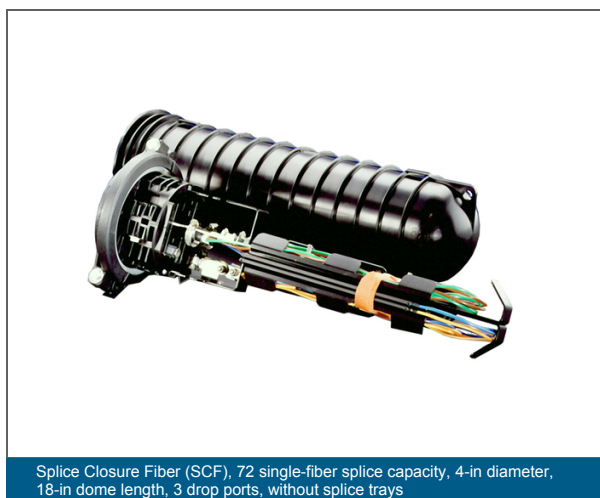

Splice Closure Fiber (SCF), 72 single-fiber splice capacity, 4-in diameter, 18-in dome length, 3 drop ports, without splice trays

Splice Closure Fiber (SCF) 72 single-fiber splice capacity, 4-in diameter, 18-in dome length, 3 drop ports, without splice trays

CORNING

Specifications

General Specifications

Application	Carrier Networks, CATV Environments, Fiber to the Premises
Mounting Type	Pole-mount, Wall-Mountable

Standards

RoHS	Free of hazardous substances according to RoHS 2011/65/EU
Design and Test Criteria	Telcordia GR-771 tested

Design

Fiber Management Configuration	Full slack storage basket - tray stacker
Ground Feed Through Cable Entries	1
Number of Ports	5
SCF Type	4 in canister, 18 in LID
Splice Tray Stacker Configuration	0.2-in tray height (single fiber)

Dimensions

Height	483 cm
Width	117 in
Depth	127 cm
Weight	2.72 kg

Ordering Information

Product Number	SCF-4C18-01
Shipping Weight	3.63 kg
Shipping Width	16.2 cm
Shipping Depth	58.4 cm

Splice Closure Fiber (SCF) 72 single-fiber splice capacity, 4-in diameter, 18-in dome length, 3 drop ports, without splice trays



Ordering Information	
Units per Delivery	1/1



Corning Optical Communications LLC • 4200 Corning Place • Charlotte, NC • 28216 • United States
800-743-2675 • FAX: 828-325-5060 • International: +1-828-901-5000 • www.corning.com/opcomm

A complete listing of the trademarks of Corning Optical Communications is available at www.corning.com/opcomm/trademarks. All other trademarks are the properties of their respective owners. Corning Optical Communications is ISO 9001 certified. © 2026 Corning Optical Communications. All rights reserved.